

K 系列托架 - K14

选型说明

例: **K 14 - J 10 - 05F - B5**



①托架回转方式

代码	内置弹簧	
	J	K
说明	可回转	防回转

②缓冲行程

代码	10	20	30	50
说明	10mm	20mm	30mm	50mm

单位: mm


③吸盘端口处连接规格

代码	内螺纹 F		外螺纹 M		
	05	05	06	08	01
说明	M5X0.8	M5X0.8	M6X1	M8X1.25	G1/8

吸盘端口 - 内螺纹

规格型号	参数							结构
	缓冲行程 S	B	A	安装螺纹	吸盘端口处连接规格	真空接口规格	弹簧力度 N	
K14-J10-05F-B5	10	73	50	M14X1	M5X0.8	M5X0.8	2~4	J 可回转
K14-J20-05F-B5	20	83	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-J30-05F-B5	30	93	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-J50-05F-B5	50	138	75	M14X1	M5X0.8	M5X0.8	2~4	K 防回转
K14-K10-05F-B5	10	73	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-K20-05F-B5	20	83	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-K30-05F-B5	30	93	50	M14X1	M5X0.8	M5X0.8	2~4	K 结构
K14-K50-05F-B5	50	138	75	M14X1	M5X0.8	M5X0.8	2~4	


单位: mm

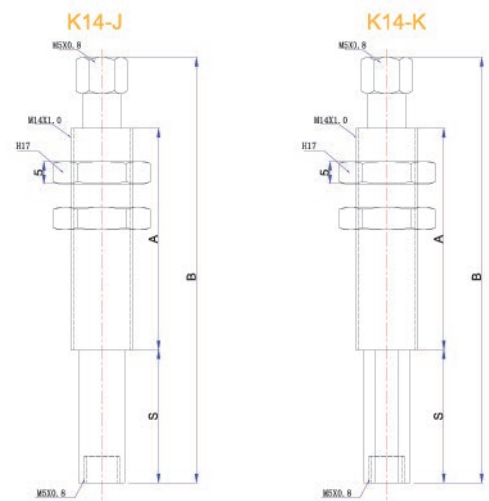

吸盘端口 - 外螺纹

规格型号	参数							结构
	缓冲行程 S	B	A	安装螺纹	吸盘端口处连接规格	真空接口规格	弹簧力度 N	
K14-J10-05M-B5	10	73	50	M14X1	M5X0.8	M5X0.8	2~4	J 可回转
K14-J20-05M-B5	20	83	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-J30-05M-B5	30	93	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-J50-05M-B5	50	138	75	M14X1	M5X0.8	M5X0.8	2~4	K 防回转
K14-K10-05M-B5	10	73	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-K20-05M-B5	20	83	50	M14X1	M5X0.8	M5X0.8	2~4	
K14-K30-05M-B5	30	93	50	M14X1	M5X0.8	M5X0.8	2~4	K 防回转
K14-K50-05M-B5	50	138	75	M14X1	M5X0.8	M5X0.8	2~4	
K14-J10-06M-B5	10	73	50	M14X1	M6X1	M5X0.8	2~4	J 可回转
K14-J20-06M-B5	20	83	50	M14X1	M6X1	M5X0.8	2~4	
K14-J30-06M-B5	30	93	50	M14X1	M6X1	M5X0.8	2~4	
K14-J50-06M-B5	50	138	75	M14X1	M6X1	M5X0.8	2~4	K 防回转
K14-K10-06M-B5	10	73	50	M14X1	M6X1	M5X0.8	2~4	
K14-K20-06M-B5	20	83	50	M14X1	M6X1	M5X0.8	2~4	
K14-K30-06M-B5	30	93	50	M14X1	M6X1	M5X0.8	2~4	K 防回转
K14-K50-06M-B5	50	138	75	M14X1	M6X1	M5X0.8	2~4	
K14-J10-08M-B5	10	73	50	M14X1	M8X1.25	M5X0.8	2~4	J 可回转
K14-J20-08M-B5	20	83	50	M14X1	M8X1.25	M5X0.8	2~4	
K14-J30-08M-B5	30	93	50	M14X1	M8X1.25	M5X0.8	2~4	
K14-J50-08M-B5	50	138	75	M14X1	M8X1.25	M5X0.8	2~4	K 防回转
K14-K10-08M-B5	10	73	50	M14X1	M8X1.25	M5X0.8	2~4	
K14-K20-08M-B5	20	83	50	M14X1	M8X1.25	M5X0.8	2~4	
K14-K30-08M-B5	30	93	50	M14X1	M8X1.25	M5X0.8	2~4	K 防回转
K14-K50-08M-B5	50	138	75	M14X1	M8X1.25	M5X0.8	2~4	
K14-J10-01M-B5	10	73	50	M14X1	G01	M5X0.8	2~4	J 可回转
K14-J20-01M-B5	20	83	50	M14X1	G01	M5X0.8	2~4	
K14-J30-01M-B5	30	93	50	M14X1	G01	M5X0.8	2~4	
K14-J50-01M-B5	50	138	75	M14X1	G01	M5X0.8	2~4	K 防回转
K14-K10-01M-B5	10	73	50	M14X1	G01	M5X0.8	2~4	
K14-K20-01M-B5	20	83	50	M14X1	G01	M5X0.8	2~4	
K14-K30-01M-B5	30	93	50	M14X1	G01	M5X0.8	2~4	K 防回转
K14-K50-01M-B5	50	138	75	M14X1	G01	M5X0.8	2~4	

单位: mm

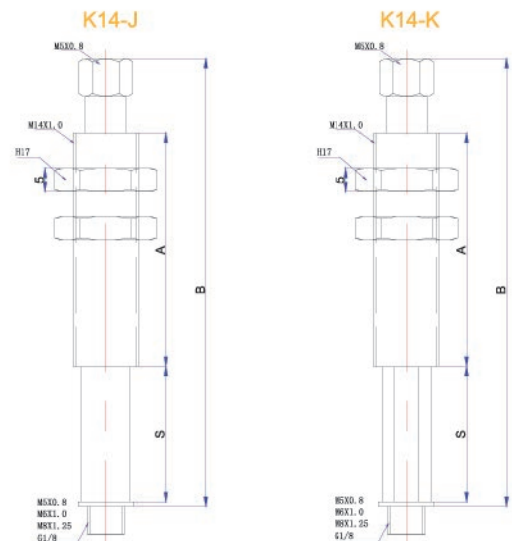

K 系列托架